

# Axygen® Maxymum Recovery® 250 µL Robotic Tips for Agilent and MGI Tech Automation Systems


CORNING

Researchers are working diligently to gain greater insight and a better understanding of SARS-CoV-2 (COVID-19). It all starts with having the right tools for the job. Robotic tips are critical for the scientific discovery process when it comes to high throughput diagnostic workflows and research-based testing for COVID-19.

The new Axxygen® Maxymum Recovery® tips have been developed to work with the Agilent/Velocity11 and MGI Tech automation systems, which can be enabled for the high throughput of magnetic bead-based RNA extraction of biological samples or pre-configured and qualified to automate high throughput pre-PCR samples.

## Features and Benefits

- ▶ Tip format: 96 tips
- ▶ Tip volume range: Up to 250 µL
- ▶ Tip material: Clear polypropylene
- ▶ RNase-/DNase-/human gDNA-free
- ▶ Non-pyrogenic
- ▶ Available options:
  - With or without aerosol-resistant filters
  - Non-sterile or sterile
  - Axxygen Maxymum Recovery surface
- ▶ Compatibility:
  - Bravo automated liquid handling platform
  - VPrep® vertical liquid handling pipetting station
  - MGISP-960
  - MGISP-100

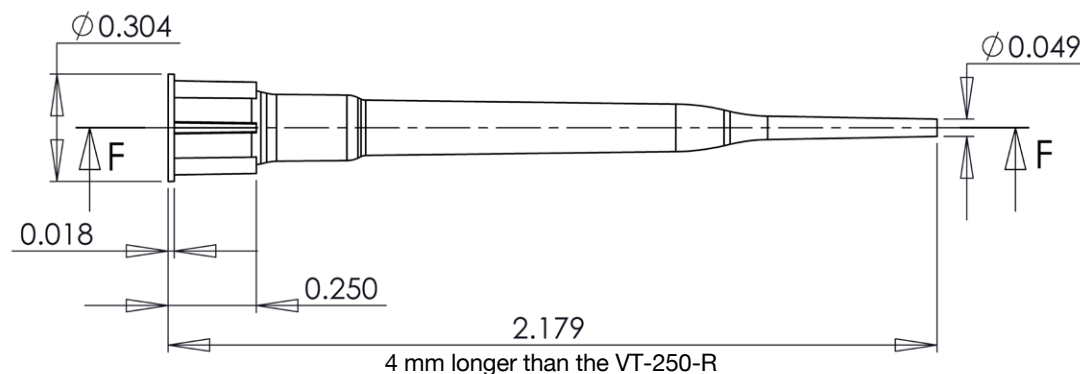

## Ordering Information

Cat. No.	Description	Qty/Cs
VTF-205-L-R-S	Axygen® Maxymum Recovery® automation tips for Agilent/Velocity11 VPrep, Bravo and MGISP-960/100: 200 µL, clear, filtered, sterile	4,800
VT-255-L-R-S	Axygen Maxymum Recovery automation tips for Agilent/Velocity11 VPrep, Bravo and MGISP-960/100: 250 µL, clear, non-filtered, sterile	4,800
VT-255-L-R	Axygen Maxymum Recovery automation tips for Agilent/Velocity11 VPrep, Bravo and MGISP-960/100: 250 µL, clear, non-filtered, nonsterile	4,800

## Related Products

Cat. No.	Description	Qty/Cs
VTF-205-R-S	Axygen automation tips for Agilent/Velocity11 VPrep, Bravo and MGISP-960/100: 200 µL, clear, pre-sterilized, filtered	4,800
VT-255-R	Axygen automation tips for Agilent/Velocity11 VPrep, Bravo and MGISP-960/100: 250 µL, clear, non-filtered, nonsterile	4,800
VT-255-R-S	Axygen automation tips for Agilent/Velocity11 VPrep, Bravo and MGISP-960/100: 250 µL, clear, non-filtered, sterile	4,800

For more specific information on claims, visit the Certificates page at [www.corning.com/lifesciences](http://www.corning.com/lifesciences).

**Warranty/Disclaimer:** Unless otherwise specified, all products are for research use only. Not intended for use in diagnostic or therapeutic procedures. Corning Life Sciences makes no claims regarding the performance of these products for clinical or diagnostic applications.

Corning's products are not specifically designed and tested for COVID-19 testing. Many Corning products, though not specific to the COVID-19 test, can be used in the workflow and preparation of the test at the customer's discretion. Customers may use these products to support their claims. We cannot make any claims or statements that our products are approved for COVID-19 test either directly or indirectly. The customer is responsible for any testing, validation, and/or regulatory submissions that may be required to support the safety and efficacy of their intended application.

For additional product or technical information, visit [www.corning.com/lifesciences](http://www.corning.com/lifesciences) or call 800.492.1110. Outside the United States, call +1.978.442.2200 or contact your local Corning sales office.

# CORNING

**Corning Incorporated**  
Life Sciences

836 North St.  
Building 300, Suite 3401  
Tewksbury, MA 01876  
t 800.492.1110  
t 978.442.2200  
f 978.442.2476

[www.corning.com/lifesciences](http://www.corning.com/lifesciences)

**ASIA/PACIFIC**  
**Australia/New Zealand**  
t 61 427286832

**Chinese Mainland**  
t 86 21 3338 4338  
f 86 21 3338 4300

**India**  
t 91 124 4604000  
f 91 124 4604099

**Japan**  
t 81 3-3586 1996  
f 81 3-3586 1291

**Korea**  
t 82 2-796-9500  
f 82 2-796-9300

**Singapore**  
t 65 6572-9740  
f 65 6735-2913

**Taiwan**  
t 886 2-2716-0338  
f 886 2-2516-7500

**EUROPE**  
CSEurope@corning.com

**France**  
t 0800 916 882  
f 0800 918 636

**Germany**  
t 0800 101 1153  
f 0800 101 2427

**The Netherlands**  
t 020 655 79 28  
f 020 659 76 73

**United Kingdom**  
t 0800 376 8660  
f 0800 279 1117

**All Other European Countries**  
t +31 (0) 206 59 60 51  
f +31 (0) 206 59 76 73

**LATIN AMERICA**  
grupoLA@corning.com

**Brazil**  
t 55 (11) 3089-7400

**Mexico**  
t (52-81) 8158-8400