

Axygen® Axypet® Pro Pipettors

Color-coded for your comfort

AXYGEN

A Corning Brand




Axygen Axypet Pro Pipettors have been engineered to provide the highest levels of comfort, accuracy, and precision. The lightweight construction, contoured handle, and 4-digit counter were designed to ensure comfortable pipetting. All pipettors feature smooth plunger movement and extremely low pipetting forces to reduce wrist strain and fatigue (RSI). Colored pushbuttons enable easy size identification and reduce the risk of cross-contamination.

- ▶ Ergonomic handle design is a perfect fit for both the right and left hand
- ▶ Convenient one-hand volume setting with auto-lock system prevents accidental volume change during work
- ▶ 4-digit counter provides greater precision and is perfectly positioned for visibility at all times
- ▶ Single-channel pipettors are compatible with very narrow tubes
- ▶ Fully autoclavable and UV-resistant for sample protection against contaminations
- ▶ The multi-channel shafts retract individually for perfect tip loading and easier tip ejection
- ▶ Unique ejector lever system enables effortless tip ejection
- ▶ Easy in-lab calibration helps you quickly adjust your pipettor to various liquid types
- ▶ Individually tested and supplied with a certificate of quality

Axygen Axypet Pro Starter Kit

Axygen Axypet Pro Starter Kit contains four variable volume pipettors in the most popular and universal volumes (0.5-10 μ L, 2-20 μ L, 20-200 μ L, and 100-1000 μ L), pipettor stand for four pipettors, and 3 racks with tips.



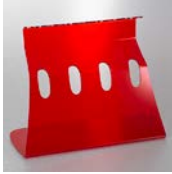

Ordering Information

Axygen® Axypet® Pro Pipettors

Single-channel

Cat. No.	Volume Range (µL)	Accuracy (%)	Precision (%)	Non-filtered Tip (µL)	Qty/Cs
AP-2-P	0.1 - 2	±40.0 to ±1.5	≤12.0 to ≤0.7	10	1
AP-10-P	0.5 - 10	±4.0 to ±1.0	≤2.8 to ≤0.4	10	1
AP-20-P	2 - 20	±3.5 to ±0.8	≤1.5 to ≤0.3	200	1
AP-50-P	5 - 50	±3.5 to ±0.8	≤1.3 to ≤0.3	200	1
AP-100-P	10 - 100	±3.0 to ±0.8	≤1.0 to ≤0.2	200	1
AP-200-P	20 - 200	±2.0 to ±0.6	≤0.7 to ≤0.2	200	1
AP-1000-P	100 - 1000	±2.5 to ±0.6	≤0.6 to ≤0.2	1000	1

8-channel

AP-8-10-P	0.5 - 10	±10.0 to ±2.0	≤8.0 to ≤1.2	10	1
AP-8-50-P	5 - 50	±4.0 to ±1.6	≤2.5 to ≤0.6	200	1
AP-8-200-P	10 - 200	±5.0 to ±1.0	≤3.0 to ≤0.6	200/300	1
AP-8-300-P	30 - 300	±3.0 to ±1.0	≤1.5 to ≤0.6	300	1

12-channel

AP-12-10-P	0.5 - 10	±10.0 to ±2.0	≤8.0 to ≤1.2	10	1
AP-12-50-P	5 - 50	±4.0 to ±1.6	≤2.5 to ≤0.6	200	1
AP-12-200-P	10 - 200	±5.0 to ±1.0	≤3.0 to ≤0.6	200/300	1
AP-12-300-P	30 - 300	±3.0 to ±1.0	≤1.5 to ≤0.6	300	1

Axygen Axypet Pro Starter Kit

Cat. No.	Description	Qty/Cs
AP-STR-KIT-P	Axygen Axypet Pro Starter Kit Includes: 4 single-channel pipettors: 0.5 to 10 µL (Cat. No. AP-10-P), 2 to 20 µL (Cat. No. AP-20-P), 20 to 200 µL (Cat. No. AP-200-P), 100 to 1000 µL (Cat. No. AP-1000-P); universal linear stand for four single-channel pipettors (Cat. No. AP-USD4-P); Axxygen MultiRack pipet tips: 10 µL (Cat. No. MR-10XT-R), 200 µL (Cat. No. MR-200-R), 1000 µL (Cat. No. MR-1000XT-R)	1

Accessories

Cat. No.	Description	Qty/Cs
AP-USD	Pipettor stand for one single-channel, 8-channel, or 12-channel pipettor	1
AP-USD4-P	Universal linear stand for four pipettors, red (four single-channel, maximum of two 8-channel or 12-channel pipettors)	1
AP-USD4	Universal linear stand for four pipettors, transparent (four single-channel, maximum of two 8-channel or 12-channel pipettors)	1
AP-USD6	Universal linear stand for six pipettors, transparent (six single-channel, maximum of three 8-channel or 12-channel pipettors)	1

Warranty/Disclaimer: Unless otherwise specified, all products are for research use only. Not intended for use in diagnostic or therapeutic procedures. Corning Life Sciences makes no claims regarding the performance of these products for clinical or diagnostic applications.

For additional product or technical information, visit www.corning.com/lifesciences or call 800.492.1110. Outside the United States, call +1.978.442.2200 or contact your local Corning sales office.

CORNING

Corning Incorporated
Life Sciences

836 North St.
Building 300, Suite 3401
Tewksbury, MA 01876
t 800.492.1110
t 978.442.2200
f 978.442.2476

www.corning.com/lifesciences

ASIA/PACIFIC
Australia/New Zealand
t 61 427286832

Chinese Mainland
t 86 21 3338 4338
f 86 21 3338 4300

India
t 91 124 4604000
f 91 124 4604099

Japan
t 81 3-3586 1996
f 81 3-3586 1291

Korea
t 82 2-796-9500
f 82 2-796-9300

Singapore
t 65 6572-9740
f 65 6735-2913

Taiwan
t 886 2-2716-0338
f 886 2-2516-7500

EUROPE
CSEurope@corning.com

France
t 0800 916 882
f 0800 918 636

Germany
t 0800 101 1153
f 0800 101 2427

The Netherlands
t 020 655 79 28
f 020 659 76 73

United Kingdom
t 0800 376 8660
f 0800 279 1117

All Other European Countries
t +31 (0) 206 59 60 51
f +31 (0) 206 59 76 73

LATIN AMERICA
grupoLA@corning.com

Brazil
t 55 (11) 3089-7400

Mexico
t (52-81) 8158-8400