

# Universal Routing Kit

CORNING


Universal Routing Kit for 24 and 36 Fiber Loose Tube Cable.  
Examples: ALTOS HD and MiniXtend

## Features and Benefits

**Snap-together furcation**  
Eliminates epoxy

---

**Fiber routing capabilities**  
Fusion Splicing  
Direct Termination

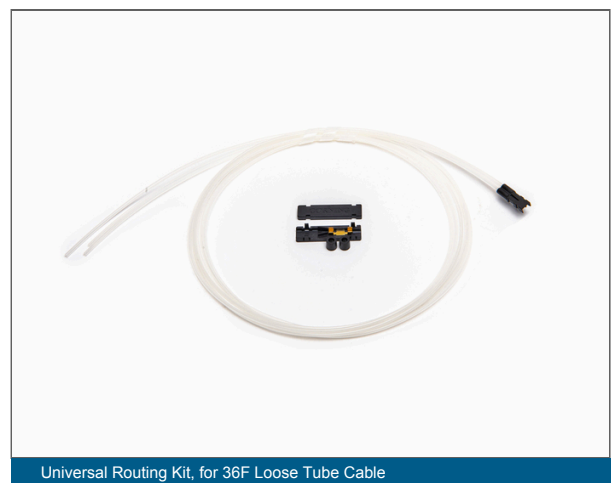

# Universal Routing Kit

CORNING

Standards	
RoHS	Free of hazardous substances according to RoHS 2011/65/EU

## Specifications

General Specifications	
Product Type	Fan-out Kits
Environment	Indoor
Fanout Type	Routing Kit

Environmental Conditions	
Temperature Range, Operation	-40 °C - 70 °C (-40 °F - 158 °F)

Mechanical Specifications Fanout Kit	
Furcation Length	Tubing Length
59 in	1499 mm

Design Fanout Kits		
Part Number	Fan-Out Tubing Color	Fiber Count
FUR-24F	Clear	24
FUR-36F	Clear	36



Corning Optical Communications LLC • 4200 Corning Place • Charlotte, NC • 28216 • United States  
800-743-2675 • FAX: 828-325-5060 • International: +1-828-901-5000 • [www.corning.com/opcomm](http://www.corning.com/opcomm)

A complete listing of the trademarks of Corning Optical Communications is available at [www.corning.com/opcomm/trademarks](http://www.corning.com/opcomm/trademarks). All other trademarks are the properties of their respective owners. Corning Optical Communications is ISO 9001 certified. © 2024 Corning Optical Communications. All rights reserved.