

Metro Scenario: Copper- and Fibre-based Cabling Solution


Copper- and fibre-based cabling solution with B2ca CPR certified (up to 120 m with A-XR outdoor copper cable and KS500S jack)



CCXSCB-LB047-C003-L7
S/FTP, 1200 MHz, AWG22, Cat.7_A, 4P Simplex, B2ca, s1a, d1, a1, up to 120 m with KS500S Jack



KAXBSM-00104-C001-BP KS500S
Shielded Jack Cat.6_A, Keystone, Pack of 24

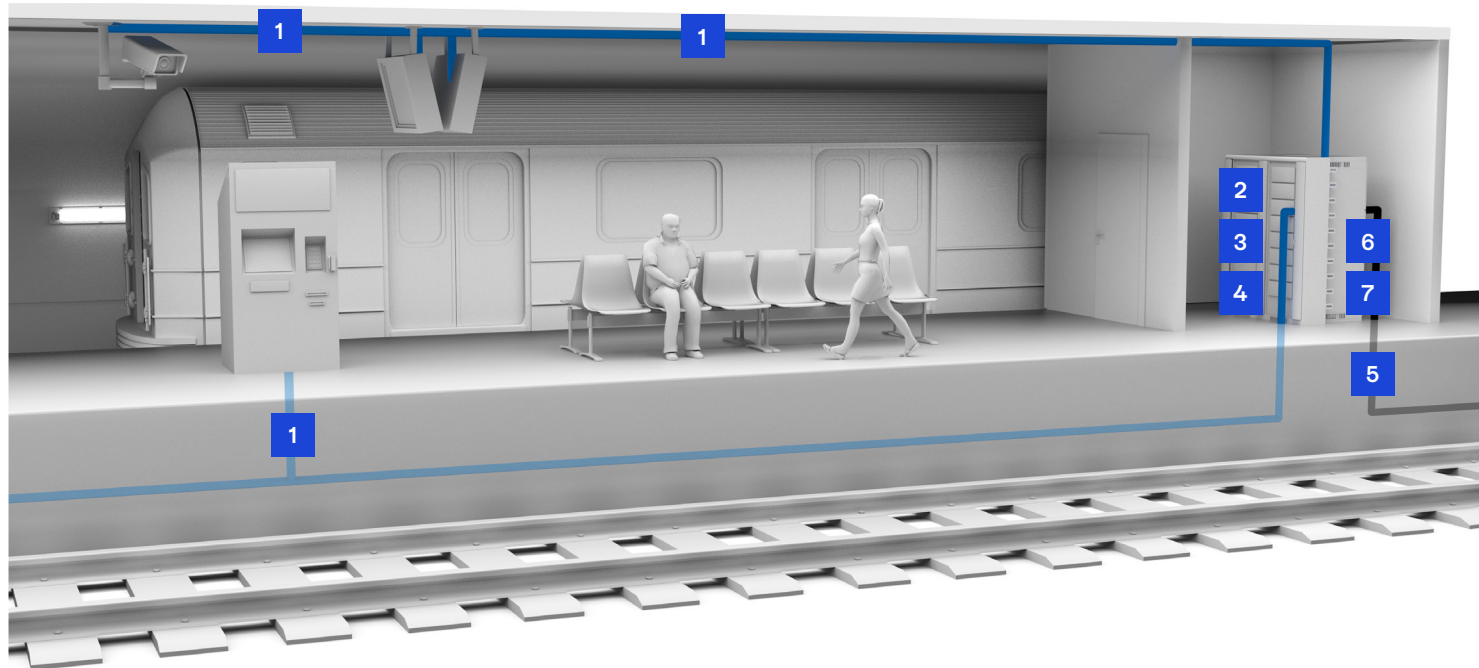

KAXCSV-02408-C001
Corning® Everon® Copper Datacom Keystone Patch panel 19 in, 1U



CCAAGB-G2002-A010-C0
Corning Everon Copper Datacom Patch Cord, Cat.6_A



xxxZPU-T3F20D2C FREEDM™ B2 Loose Tube Indoor/Outdoor Cable, B2ca certified, 12F to 192F



LAN1-xxAE-PGTL-B
Everon LAN1 Fibre Housings, Splice Housing with Adapters, Splice Cassettes and Pigtails (PGTL), 12F to 96F



F040402E2Z200002M / F040402G2Z200002M
LC UPC Duplex – LC UPC Duplex Fibre Patch Cord