
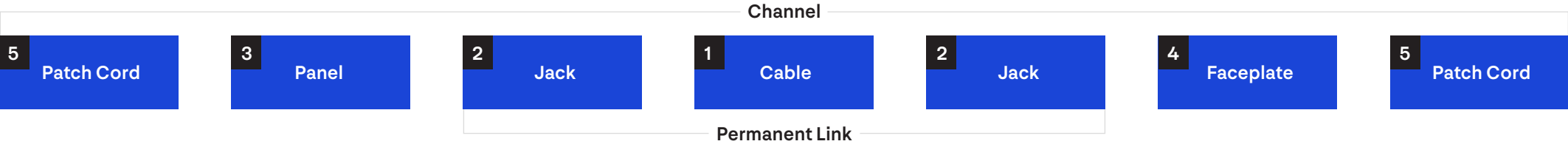
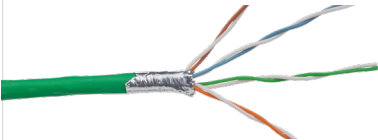


VOL Footprint V500S & E500S Shielded Cat.6_A/Class EA, Southern Europe

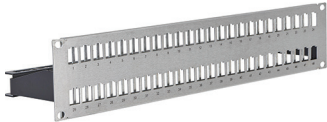

1Cables	2Jacks	3Panels	4Faceplates and Outlets	5Patch Cords
 CCXEDB-DB047-C001-L7 Cat.6_A SFTP LSZH™, 4-Pairs, 23 AWG, B2ca, blue, 1,000 m CCXEDB-DC047-C001-L6 Cat.6_A SFTP LSZH, 4-Pairs, 23 AWG, Cca, blue, 500 m CCXEDA-DC047-C001-L6 Cat.6_A FFTP LSZH, 4-Pairs, 23 AWG, Cca, blue, 500 m	 XF500003553 RJ45 Cat.6_A STP Jack, silver (bag of 8), V500S, VOL-OCK6A-SN8 XF500003546 RJ45 Cat.6_A STP Jack, silver (bulk pack of 480), V500S, VOL-OCK6A-SNV	 MAXCSV-02408-C001 Black Patch Panel, 24 ports, 1U MAXCSV-02400-C001 Silver Patch Panel, 24 ports, 1U MAXCSV-02401-C001 White Patch Panel, 24 ports, 1U	 UAXCSE-V0101-C031-BP 22.5 x 45 mm Inclined Adapter for one jack UAXCSE-V0101-C,030-BP 45 x 45 mm Inclined Adapter for one jack UAXCSE-V0201-C030-BP 45 x 45 mm Inclined Adapter for two jacks CAXCSE-00101-C031-BP 45 x 45 mm Faceplate for one adapter CAXCSE-00101-C030-BP 22.5 x 45 mm Blank cover	 CCAAGB-G1002-A005-C0 Cat.6_A SFTP LSZH, grey, 0.5 m CCAAGB-G1002-A010-C0 Cat.6_A SFTP LSZH, grey, 1 m CCAAGB-G1002-A020-C0 Cat.6_A SFTP LSZH, grey, 2 m CCAAGB-G1002-A030-C0 Cat.6_A SFTP LSZH, grey, 3 m CCAAGB-G1002-A050-C0 Cat.6_A SFTP LSZH, grey, 5 m CCAAGB-G1002-A100-C0 Cat.6_A SFTP LSZH, grey, 10 m Additional lengths and colours are available. Please consult your local Corning representative or alternatively Corning Customer Care at 00800-2676-4641 or email cc.emea@corning.com.
 UU009175728 Cat.6_A FUTP LSZH, 4-Pairs, 24 AWG, B2ca, green, 500 m UU009175736 Cat.6_A FUTP LSZH, 4-Pairs, 24 AWG, Cca, green, 500 m	 DE010022734 RJ45 Cat.6_A STP Jack, silver (bag of 8), E500S, OCK6AS-E8 DE010022742 RJ45 Cat.6_A STP Jack, silver (bulk pack of 480), E500S, OCK6AS-EV	 UU001622909 Black Patch Panel, 48 ports, 2U VOL-PPCBF48K UU001622933 Silver Patch Panel, 48 ports, 2U VOL-PPCBF48K		