


Rapid Deployment, New Sites, Connectorised Components

New fibre node with splitters, pre-terminated to multifibre OptiTip® connectors. Plug & Play™ multiport connectorised block terminal (CBT) with OptiTip terminated tail cable.

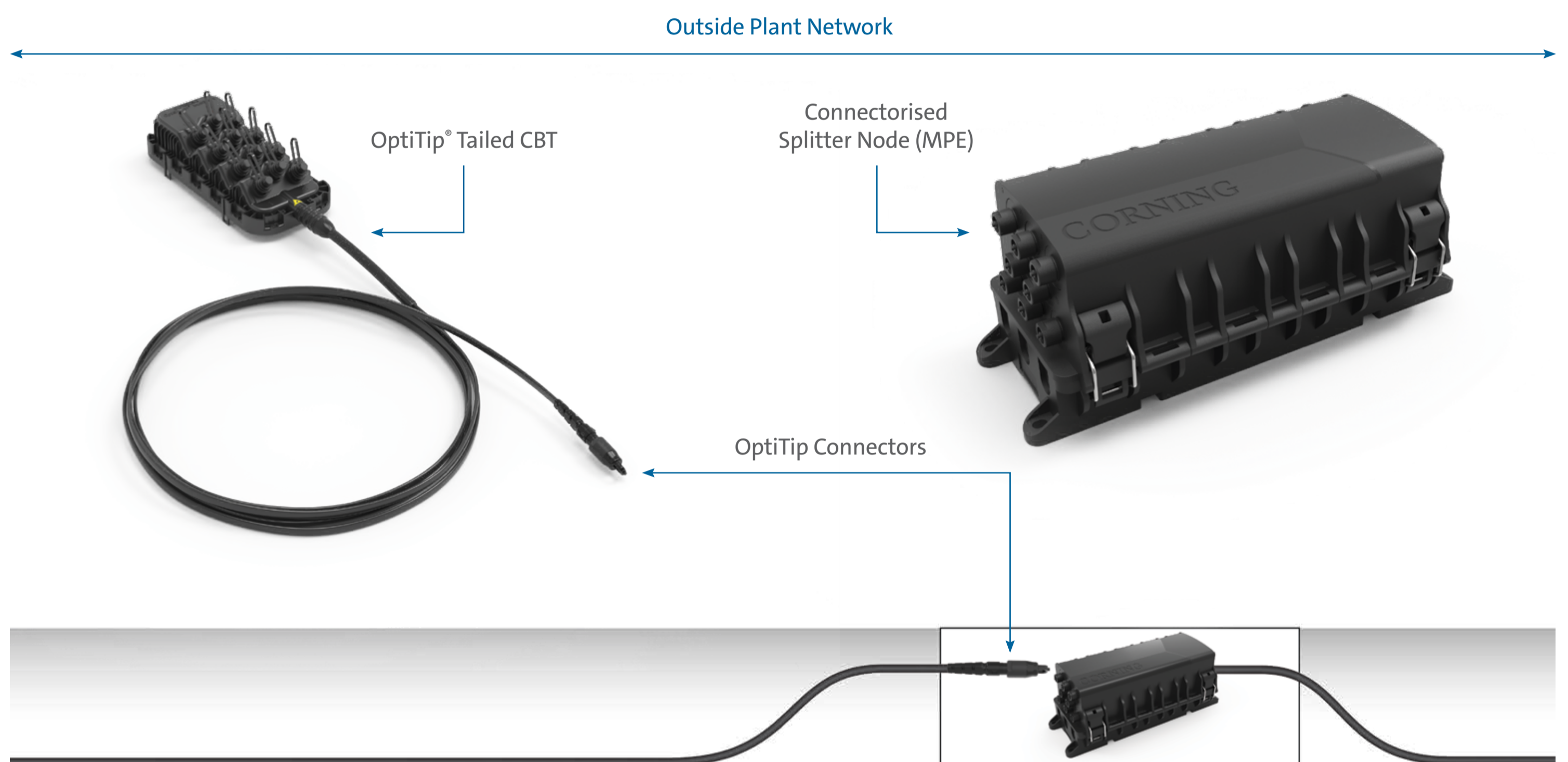

OptiTip Tailed Multiport CBT

Features and Tips:

- CBT with a cable terminated with a multifibre OptiTip connector.
- Uses standard OptiTap® single-fibre output ports so that standard single and double-ended OptiTap drop cables can be installed.
- Available with tail cable lengths of 5, 20, 50, 80, 110, 140, 170, 200, 230, 260, 290, 320 and 350 metres.
- Tail cable slack stored in joint box with CBT.
- The OptiTip connector on the CBT tail does not need cleaning before plugging it into the MPE unless it is known to be contaminated.

Connectorised Splitter Node (MPE)

Features and Tips:

- Includes one or two 2x32 way splitters for up to 64 end-customer connections.
- Splitter output legs pre-terminated to multifibre OptiTip connectors.
- Enables OptiTip tailed CBTs to be plugged directly into the node.
- OptiTip CBTs can be installed in less than two minutes.
- Contains six splice trays each supporting 24 fibres and splices.
- Enables loop through and branching of cables.
- Always clean the OptiTip connectors on the MPE before plugging in the CBT.