


Corning® 384 Well Clear Fibronectin Coated Microplate

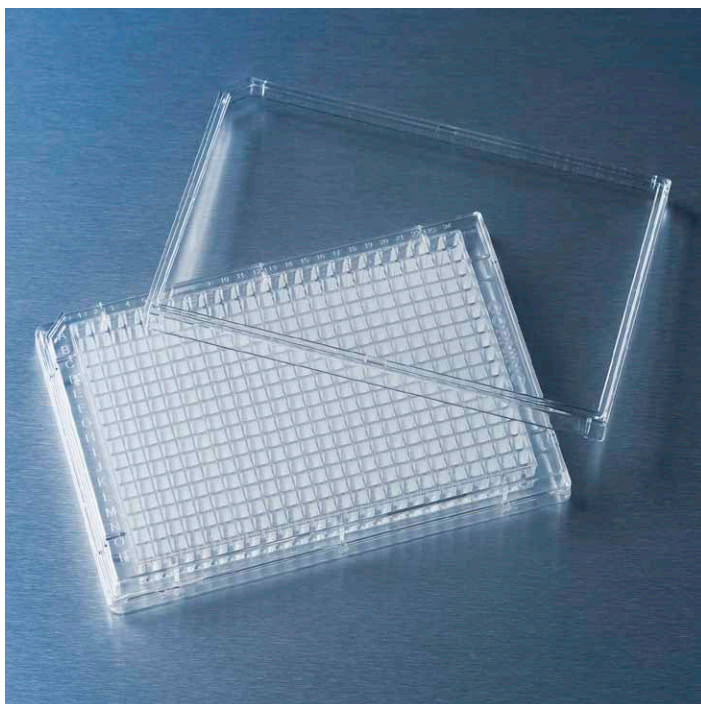

Cat. No. 3847

Product Details

Material	Polystyrene
Quantity/Pack	20
Quantity/Case	100
Plate Format	384 well
Plate Feature	Standard
Plate Color	Clear
Well Bottom	Flat
Well Bottom Color	Clear
Well Shape	Square
Well Volume	112 μ L
Cell Growth Area	0.06 cm ²
Recommended Medium Well Volume	25-50 μ L
Recommended Working Volume	20-80 μ L
Surface Treatment	Fibronectin
Sterile	No
Lids Included	Yes

- ▶ Ideal for promoting cell attachment, proliferation and differentiation of a variety of cell types.
- ▶ Coating uniformity promotes consistent data.
- ▶ Fibronectin used for coating is purified from human donor plasma that has been tested negative for HBsAg, HIV-I, HIV-II and HCV antibodies.
- ▶ Quality control testing ensures better performance and consistency.

CORNING



Beginning-to-end Solutions for Drug Discovery

At Corning, we continuously strive towards improving efficiencies and developing new products and technologies for life science researchers. From assay preparation to storage, our technical experts understand your challenges and your increased need for high-quality products.

It is this expertise, plus a 160 year legacy of Corning innovation and manufacturing excellence, that puts us in a unique position to be able to offer a beginning-to-end portfolio of high-quality, reliable life sciences consumables.

For additional product or technical information, please visit www.corning.com/lifesciences or call 800.492.1110. Customers outside the United States, call 1.978.442.2200 or contact your local Corning sales office listed below.

Corning Incorporated Life Sciences

836 North St.
Building 300, Suite 3401
Tewksbury, MA 01876
t 800.492.1110
t 978.442.2200
f 978.442.2476

www.corning.com/lifesciences

Worldwide Support Offices

ASIA / PACIFIC
Australia/New Zealand
t 0402-794-347

China
t 86 21 2215 2888
f 86 21 6215 2988

India
t 91 124 4604000
f 91 124 4604099

Japan
t 81 3-3586 1996
f 81 3-3586 1291

Korea
t 82 2-796-9500
f 82 2-796-9300

Singapore
t 65 6733-6511
f 65 6861-2913

Taiwan
t 886 2-2716-0338
f 886 2-2516-7500

EUROPE

France
t 0800 916 882
f 0800 918 636

Germany
t 0800 101 1153
f 0800 101 2427

The Netherlands
t 31 20 655 79 28
f 31 20 659 76 73

United Kingdom
t 0800 376 8660
f 0800 279 1117

All Other European Countries

t 31 (0) 20 659 60 51
f 31 (0) 20 659 76 73

LATIN AMERICA Brasil

t (55-11) 3089-7419
f (55-11) 3167-0700

Mexico
t (52-81) 8158-8400
f (52-81) 8313-8589

The Corning Family of Brands

CORNING costar cellgro PYREX AXIGEN GOSSELIN™

For a listing of trademarks, visit us at www.corning.com/lifesciences/trademarks.
Corning Incorporated, One Riverfront Plaza, Corning, NY 14831-0001